

Series 6500 booster

Parts list


File No: 6062.103

Date: FEBRUARY 20, 2014


Supersedes: NEW

Date: NEW

Series 6500 Booster

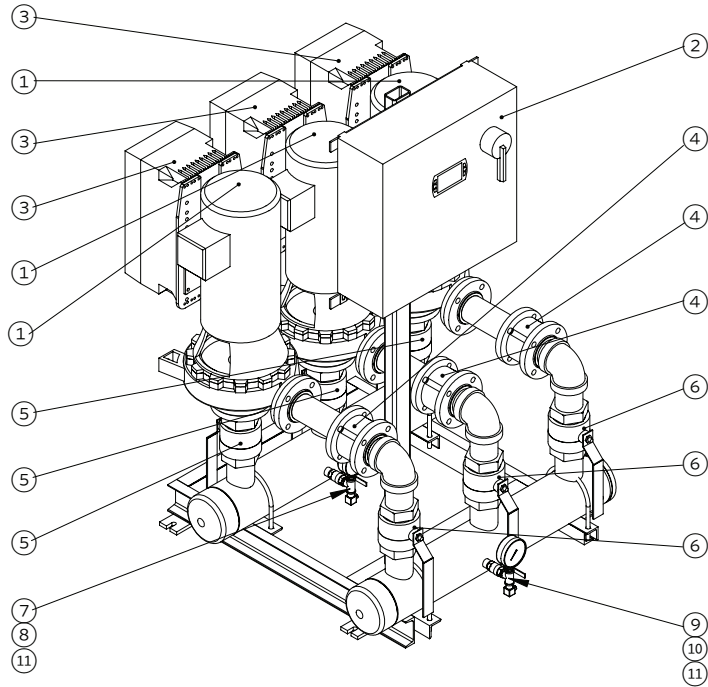

6535IVS

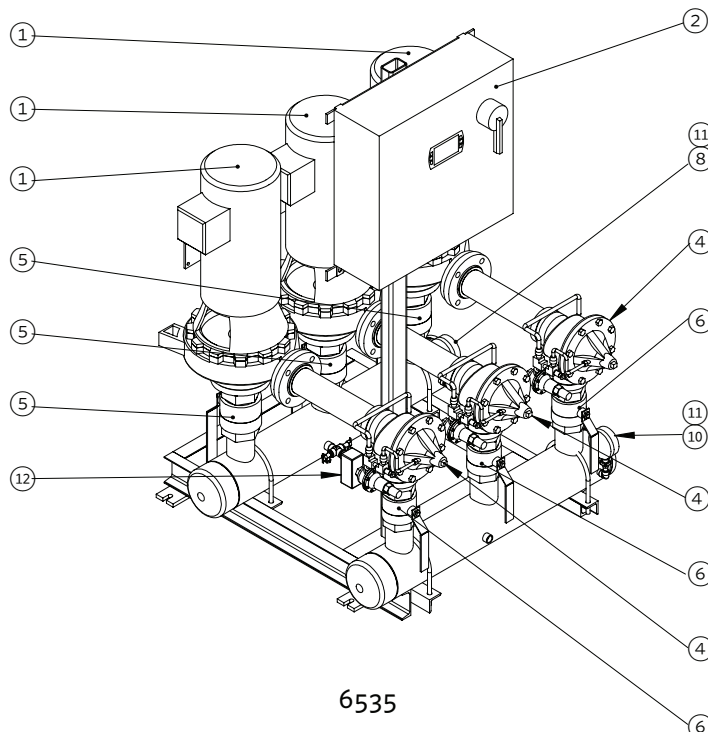

6535

ITEM 1: PUMP

See File no. 6042.127 for 4280 pump parts

6500 SERIES BOOSTER MODEL	PART NUMBER	QTY PER BOOSTER
6525	4280	2
6535	4280	3

ITEM 2: CONTROL PANEL

Please contact Armstrong service department with unit serial number for replacement control panel

ITEM 3: IVS DRIVE

See File no. 6094.100 for ivs drive parts

*ivs systems only.

ITEM 4: MAIN CHECK VALVE / MAIN PRV

VALVE SIZE	CHECK VALVE PART NUMBER*	PRV PART NUMBER†	QTY PER PUMP
1.5"	D975040-506	D975030-006	1
2"	D975040-507	D975030-007	1
2.5"	D975041-108	D975030-008	1
3"	D975041-109	D975030-009	1

* 1.5" and 2" are female NPT, 2.5" and 3" are wafer type.

† All sizes are female NPT.

ITEM 5: SUCTION ISOLATION VALVE

VALVE SIZE	PART NUMBER	QTY PER PUMP
1.5"	D975000-006	1
2"	D975000-007	1
2.5"	D975000-008	1
3"	D975000-009	1

ITEM 6: DISCHARGE ISOLATION VALVE

VALVE SIZE	PART NUMBER	QTY PER PUMP
1.5"	D975000-006	1
2"	D975000-007	1
2.5"	D975000-008	1
3"	D975000-009	1

4

ITEM 7: SUCTION TRANSDUCER*

PRESSURE RANGE	PART NUMBER	QTY PER BOOSTER
0-300 PSI	D500400-202	1

* ivs systems only.

ITEM 8: SUCTION GAUGE

PRESSURE RANGE	PART NUMBER	QTY PER BOOSTER
0 to 60 PSI	975005-810	1
0 to 160 PSI	975005-811	1

ITEM 9: DISCHARGE TRANSDUCER*

PRESSURE RANGE	PART NUMBER	QTY PER BOOSTER
0 to 300 PSI	D500400-202	1
0 to 500 PSI	D500400-203	1

* ivs systems only.

ITEM 10: DISCHARGE GAUGE

PRESSURE RANGE	PART NUMBER	QTY PER BOOSTER
0 to 60 PSI	975005-810	1
0 to 160 PSI	975005-811	1
0 to 300 PSI	975005-812	1
0 to 400 PSI	975005-813	1

ITEM 11: GAUGE ASSEMBLY ISOLATION VALVE

PRESSURE RANGE	PART NUMBER*	QTY PER BOOSTER
ALL	D975000-700	2

* Female NPT.

ITEM 12: AQUASTAT†

PRESSURE RANGE	PART NUMBER	QTY PER BOOSTER
ALL	425648-001	1

† Constant speed systems only.

TORONTO
+1 416 755 2291

BUFFALO
+1 716 693 8813

BIRMINGHAM
+44 (0) 8444 145 145

MANCHESTER
+44 (0) 8444 145 145

BANGALORE
+91 (0) 80 4906 3555

SHANGHAI
+86 21 3756 6696