


ARMkool 6 Horizontal No Options

SUBMITTAL

JOB: _____	REPRESENTATIVE: _____
_____	_____
_____	_____
ENGINEER: _____	ORDER NO: _____ DATE: _____
CONTRACTOR: _____	SUBMITTED BY: _____ DATE: _____
	APPROVED BY: _____ DATE: _____

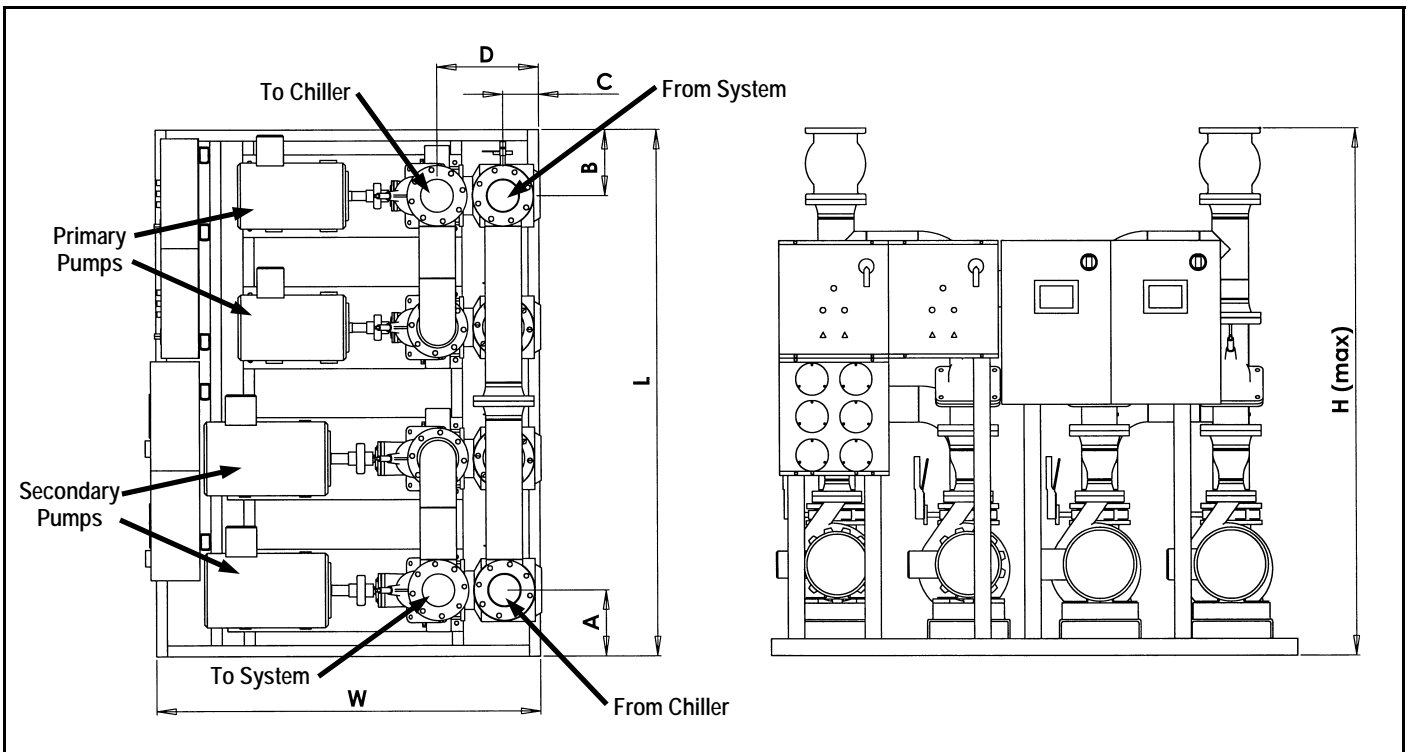

DIMENSIONS inches (mm)							
	W	L	H (max)	A	B	C	D
ARMkool 6 FS H P115 S115 NC S	72 (1829)	93 (2362)	87 (2210)	10.5 (267)	10.5 (267)	6.75 (172)	18.75 (476)
ARMkool 6 FS H P225 S225 NC S	72 (1829)	93 (2362)	91 (2311)	10.5 (267)	10.5 (267)	6.75 (172)	18.75 (476)
ARMkool 6 FS H P330 S330 NC S	72 (1829)	105 (2667)	91 (2311)	12.0 (305)	12.0 (305)	6.00 (152)	19.50 (495)
ARMkool 6 FS H P440 S440 NC S	76 (1930)	105 (2667)	91 (2311)	12.0 (305)	12.0 (305)	6.75 (172)	18.75 (476)

WEIGHT lbs. (kg)		
	Fixed Speed	Variable Speed
ARMkool 6 FS H P115 S115 NC S	6430 (2923)	6798 (3090)
ARMkool 6 FS H P225 S225 NC S	6826 (3103)	7194 (3270)
ARMkool 6 FS H P330 S330 NC S	7000 (3182)	7457 (3390)
ARMkool 6 FS H P440 S440 NC S	8172 (3715)	8774 (3988)

Armstrong Pumps Inc.
 93 East Avenue
 North Tonawanda, New York
 U.S.A. 14120-6594
 Tel: (716) 693-8813
 Fax: (716) 693-8970

S.A. Armstrong Limited
 23 Bertrand Avenue
 Toronto, Ontario
 Canada, M1L 2P3
 Tel: (416) 755-2291
 Fax: (416) 759-9101



Armstrong Pumps Limited
 Peartree Road, Stanway
 Colchester, Essex
 United Kingdom, CO3 0LP
 Tel: 01206-579491
 Fax: 01206-760532

Armstrong Darling
 2200 Place Transcanadienne
 Montreal, Quebec
 Canada, H9P 2X5
 Tel: (514) 421-2424
 Fax: (514) 421-2436

