


## ARMkool 8 Horizontal No Options

## SUBMITTAL

JOB: _____	REPRESENTATIVE: _____
_____	_____
_____	_____
ENGINEER: _____	ORDER NO: _____ DATE: _____
CONTRACTOR: _____	SUBMITTED BY: _____ DATE: _____
	APPROVED BY: _____ DATE: _____

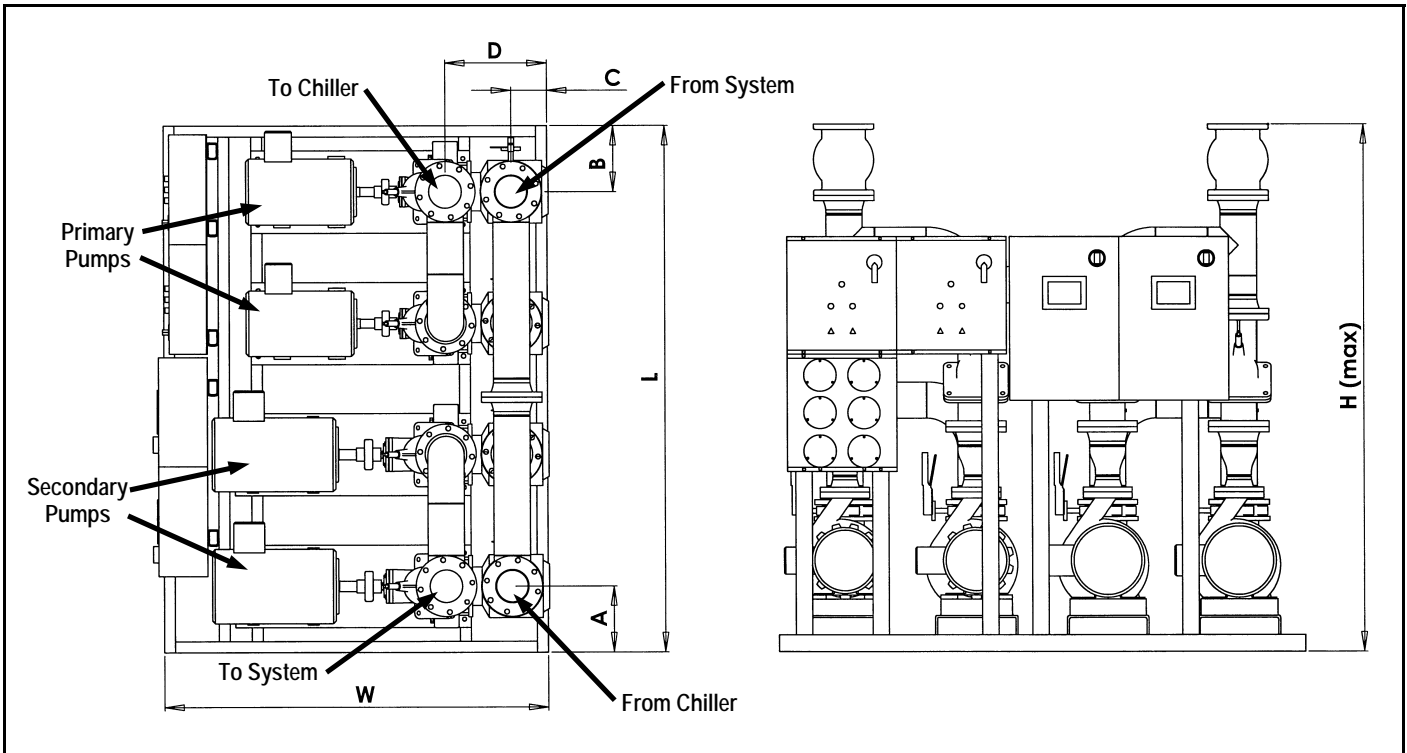

DIMENSIONS inches (mm)							
	W	L	H (max)	A	B	C	D
ARMkool 8 FS H P530 S530 NC S	74 (1880)	93 (2362)	107 (2718)	10.5 (267)	10.5 (267)	6.75 (172)	20.75 (527)
ARMkool 8 FS H P640 S640 NC S	84 (2134)	105 (2667)	110 (2794)	12.0 (305)	12.0 (305)	6.75 (172)	22.75 (578)
ARMkool 8 FS H P740 S740 NC S	80 (2032)	105 (2667)	110 (2794)	12.0 (305)	12.0 (305)	8.50 (216)	22.75 (578)
ARMkool 8 FS H P850 S850 NC S	80 (2032)	105 (2667)	113 (2870)	12.0 (305)	12.0 (305)	8.50 (216)	22.75 (578)

WEIGHT lbs. (kg)		
	Fixed Speed	Variable Speed
ARMkool 8 FS H P530 S530 NC S	10156 (4616)	10613 (4824)
ARMkool 8 FS H P640 S640 NC S	11214 (5097)	11816 (5371)
ARMkool 8 FS H P740 S740 NC S	11110 (5050)	11712 (5324)
ARMkool 8 FS H P850 S850 NC S	12246 (5566)	12996 (5907)

Armstrong Pumps Inc.  
93 East Avenue  
North Tonawanda, New York  
U.S.A. 14120-6594  
Tel: (716) 693-8813  
Fax: (716) 693-8970

S.A. Armstrong Limited  
23 Bertrand Avenue  
Toronto, Ontario  
Canada, M1L 2P3  
Tel: (416) 755-2291  
Fax: (416) 759-9101



Armstrong Pumps Limited  
Peartree Road, Stanway  
Colchester, Essex  
United Kingdom, CO3 0LP  
Tel: 01206-579491  
Fax: 01206-760532

Armstrong Darling  
2200 Place Transcanadienne  
Montreal, Quebec  
Canada, H9P 2X5  
Tel: (514) 421-2424  
Fax: (514) 421-2436

